 


ProClin® 950 Preservative for Diagnostic Reagents

Product Information



Formulation

- 2-Methyl-4-isothiazolin-3-one (RH-573)
- Water

Manufacturing Specifications

- Total Active Ingredient 9.5% - 9.9%
- Appearance clear liquid
- pH on finished product 3.0 - 6.0

Physical Properties

These numbers do not constitute specifications


- Color (APHA) <100
- Specific Gravity 1.02
- Solubility
Totally miscible in water; soluble in lower alcohols and glycols; low solubility in hydrocarbons

Typical Use Levels

- 0.05 - 0.10% (w/w)
(0.05 - 0.10 mg ProClin 950 per 100 g of solution)

Shelf Life (25 °C)

- 3 years from date of manufacture

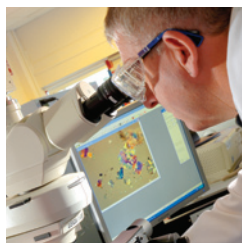

Ordering Information

Description	Cat. No.
ProClin 950 Preservative	
5 mL ampule	46885-U
50 mL bottle	46878-U
400 mL bottle	46879-U
3.6 L bottle	46883-U
17 L pail	46884-U
ProClin Reference Standard	
1 mL ampule (1.5% A.I. solution)	33360-U