

アミン類

Column : Cabowax Amine, 30 m x 0.53 mm ID, 1.0 μ m film

Cat. No. : 25353

Oven : 50 , 8 /min. to 200 (10 min.)


Inj. : 220

Det. : FID, 220

Carrier Gas : Helium, 20 cm/sec @ 170

Injection : 0.02 μ L

Sample : neat amines mix, split 100 : 1

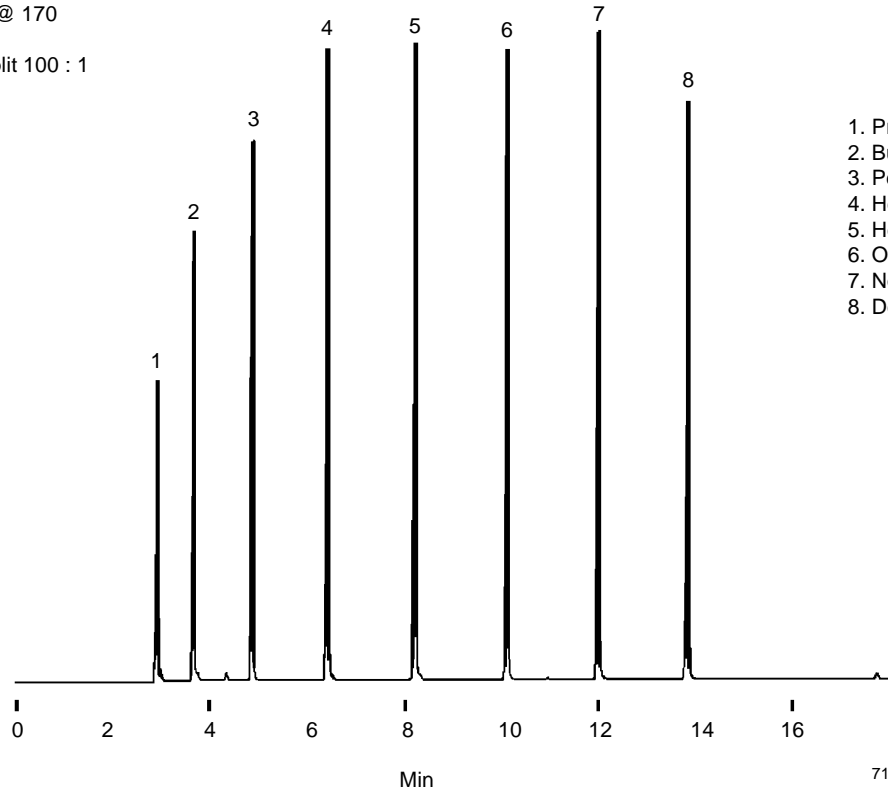

1. Propylamine
2. Butylamine
3. Pentylamine
4. Hexylamine
5. Heptylamine
6. Octylamine
7. Nonylamine
8. Decylamine