


**Bentone 34/DnDP SCOT Column**  
**30m x 0.53mm ID ( $\beta = 45$ )**

Cat. No.: 25501  
Oven: 40°C to 150°C at 8°C/min  
Carrier: helium, 10mL/min  
Det.: FID, 300°C  
Inj.: 1 $\mu$ L, 250°C, split injection

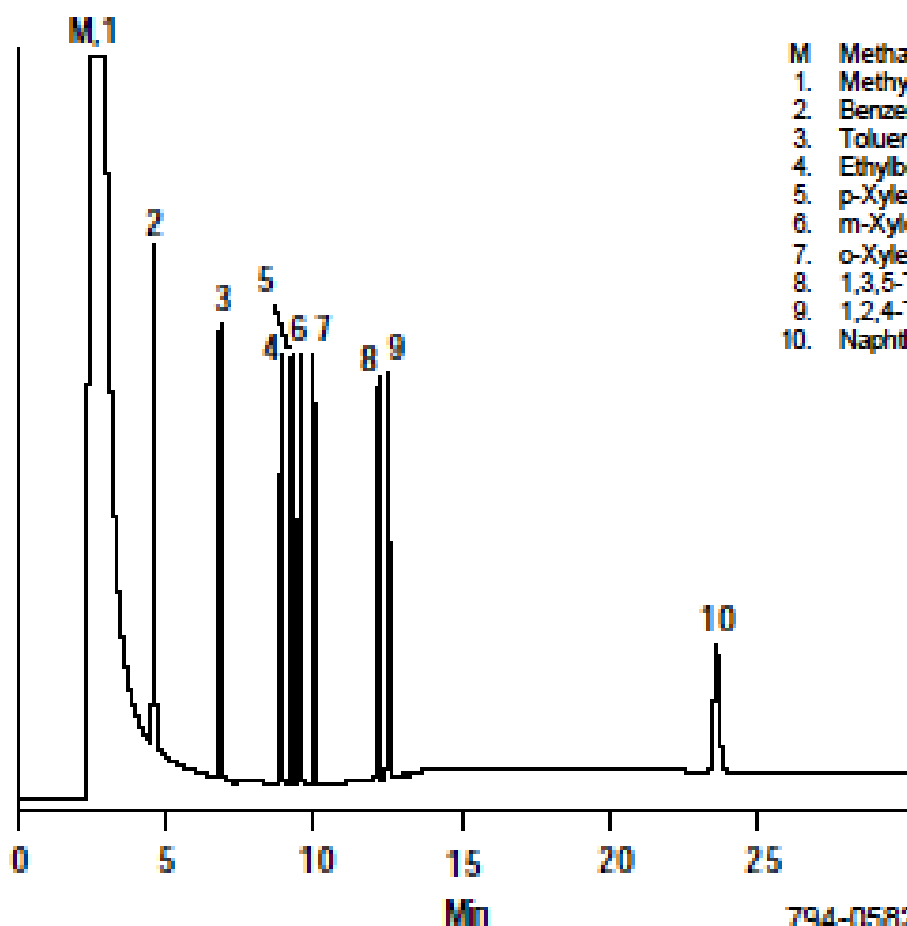

- M Methanol (solvent)
- 1. Methyltert-butylether
- 2. Benzene
- 3. Toluene
- 4. Ethylbenzene
- 5. p-Xylene
- 6. m-Xylene
- 7. o-Xylene
- 8. 1,3,5-Trimethylbenzene
- 9. 1,2,4-Trimethylbenzene
- 10. Naphthalene

794-0582