

TO-14 Gas Standards

Product Specification

These high pressure, transportable gas calibration blends for US EPA Method TO-14 ensure that laboratories can perform Method TO-14 and Clean Air Act analyses at a fraction of their former costs. These blends are available only through Supelco.

Scott TO-14 gas blends are packaged in SCOTTY® HP high pressure, transportable, laboratory-size cylinders. A SCOTTY HP cylinder measures only 12¼" high and 3¼" in diameter (31 cm x 8.3cm), but contains 104 liters of gas at 1800psi – enough gas to deliver adequate calibration for 80 or more uses. These products provide the reliability and performance of high pressure gas mixes without the maintenance and safety problems associated with large high pressure cylinders. SCOTTY HP cylinders are equipped with CGA 110/180 fittings, to plumb directly to your gas sampling system or through an appropriate regulator.

Scott TO-14 gas calibration blends are traceable to NIST reference mixtures (NIST SRM 1804), and are certified by Scott Gases for superior stability and accuracy.

Four blends are available. All products contain 100ppb each analyte in nitrogen.


Ordering Information:

Gas Calibration Blends

TO-14 Calibration Mix 1

100ppb each component in nitrogen.

Benzene	Halocarbon 12
Bromomethane	Halocarbon 113
Carbon tetrachloride	Halocarbon 114
Chlorobenzene	Hexachloro-1,3-butadiene
Chloroform	Methylene chloride
Chloromethane	Styrene
1,2-Dibromoethane	1,1,2,2-Tetrachloroethane
1,2-Dichlorobenzene	Tetrachloroethene
1,3-Dichlorobenzene	Toluene
1,4-Dichlorobenzene	1,2,4-Trichlorobenzene
1,1-Dichloroethane	1,1,1-Trichloroethane
1,2-Dichloroethane	1,1,2-Trichloroethane
1,1-Dichloroethene	Trichloroethene
cis-1,2-Dichloroethene	1,2,4-Trimethylbenzene
1,2-Dichloropropane	1,3,5-Trimethylbenzene
cis-1,3-Dichloropropene	Vinyl chloride
trans-1,3-Dichloropropene	m-Xylene
Ethyl chloride	o-Xylene
Ethylbenzene	p-Xylene
Halocarbon 11	
SCOTTY HP cylinder	41900-U

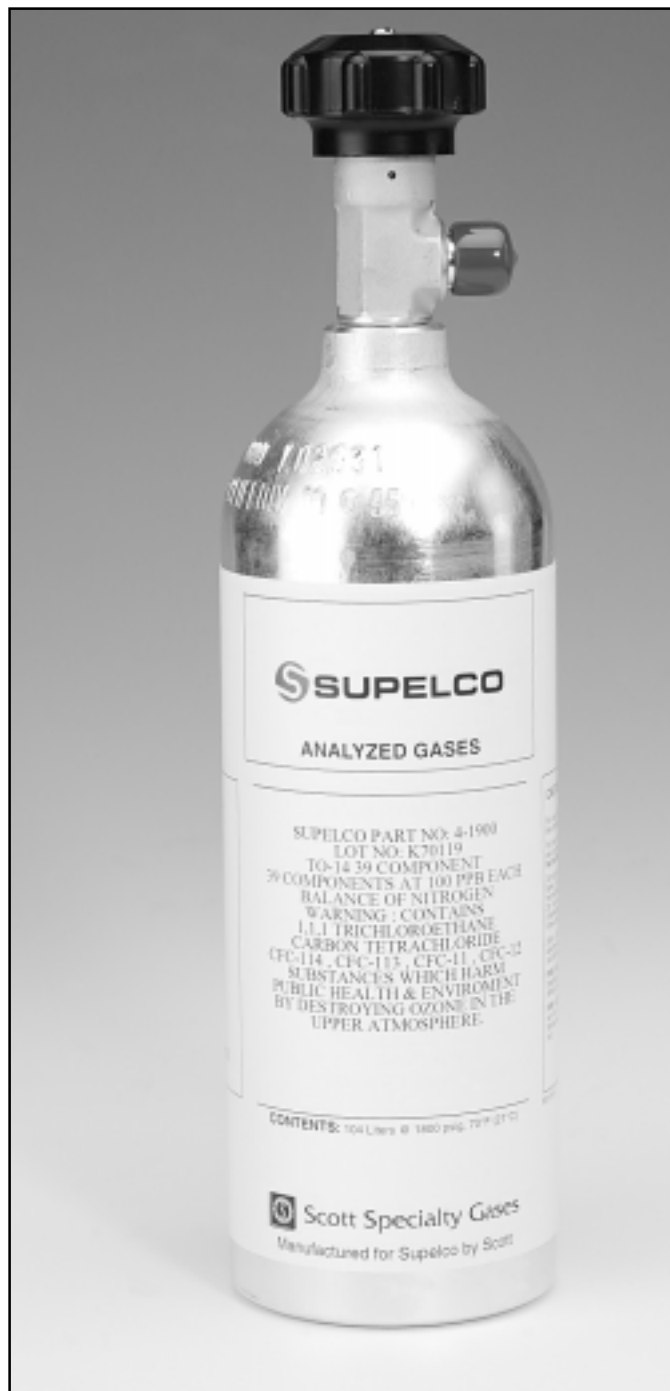

Ordering information continued on reverse side of this sheet.

TO-14 Chlorinated Hydrocarbons Subset Mix

100ppb each component in nitrogen.

Carbon tetrachloride	Ethyl chloride
Chloroform	Hexachloro-1,3-butadiene
Chloromethane	Methylene chloride
1,1-Dichloroethane	Tetrachloroethene
1,2-Dichloroethane	1,1,2,2-Tetrachloroethane
1,1-Dichloroethene	1,1,1-Trichloroethane
cis-1,2-Dichloroethene	1,1,2-Trichloroethane
1,2-Dichloropropane	Trichloroethene
cis-1,3-Dichloropropene	Vinyl chloride
trans-1,3-Dichloropropene	
SCOTTY HP cylinder	41902

TO-14 CFC/HCFC Subset Mix

100ppb each component in nitrogen.

Halocarbon 11	Halocarbon 113
Halocarbon 12	Halocarbon 114
SCOTTY HP cylinder	41903

TO-14 Aromatics Subset Mix

100ppb each component in nitrogen.

Benzene	Toluene
Chlorobenzene	1,2,4-Trichlorobenzene
1,2-Dichlorobenzene	1,2,4-Trimethylbenzene
1,3-Dichlorobenzene	1,3,5-Trimethylbenzene
1,4-Dichlorobenzene	m-Xylene
Ethylbenzene	o-Xylene
Styrene	p-Xylene
SCOTTY HP cylinder	41901

TO-14 Reactive Subset Mix

100ppb each component in nitrogen.

1,3-Butadiene	4-Ethyltoluene
3-Chloropropene	
SCOTTY HP cylinder	41911

TO-14 GC/MS Tuning Standard

2ppm bromofluorobenzene in nitrogen.

SCOTTY HP cylinder	41913
--------------------	--------------

Accessories For Use with SCOTTY HP Cylinders



994-0243

Model 6 Series Regulator with Gauge

Accepts inlet pressures up to 4000psig. **501115**

Model 26 Pressure Regulator with Gauge

For use with Scotty HP cylinders, plus high pressure gauge. **41910-U**

Model 26 Pressure Regulator

No gauge. **41907**

High Pressure Gauge

For use with Model 26 regulator. **41908**

Stand

Ensures your SCOTTY HP cylinder will be stable on a benchtop or other surface. **41909**

SCOTTY is a registered trademark of Scott Specialty Gases, Inc.

Contact our Technical Service Department

(phone 800-359-3041 or 814-359-3041, FAX 800-359-3044 or 814-359-5468) for expert answers to your questions.

For more information, or current prices, contact your nearest Supelco subsidiary listed below. To obtain further contact information, visit our website (www.sigma-aldrich.com), see the Supelco catalog, or contact Supelco, Bellefonte, PA 16823-0048 USA.

ARGENTINA · Sigma-Aldrich de Argentina, S.A. · Buenos Aires 1119 **AUSTRALIA** · Sigma-Aldrich Pty. Ltd. · Castle Hill NSW 2154 **AUSTRIA** · Sigma-Aldrich Handels GmbH · A-1110 Wien
BELGIUM · Sigma-Aldrich N.V./S.A. · B-2880 Bornem **BRAZIL** · Sigma-Aldrich Quimica Brasil Ltda. · 01239-010 São Paulo, SP **CANADA** · Sigma-Aldrich Canada, Ltd. · 2149 Winston Park Dr., Oakville, ON L6H 6J8 **CZECH REPUBLIC** · Sigma-Aldrich s.r.o. · 186 00 Praha 8 **DENMARK** · Sigma-Aldrich Denmark A/S · DK-2665 Vallensbaek Strand **FINLAND** · Sigma-Aldrich Finland/YA-Kemia Oy · FIN-00700 Helsinki **FRANCE** · Sigma-Aldrich Chimie · 38297 Saint-Quentin-Fallavier Cedex **GERMANY** · Sigma-Aldrich Chemie GmbH · D-82041 Deisenhofen **GREECE** · Sigma-Aldrich (o.m.) Ltd. · Ilioupoli 16346, Athens **HUNGARY** · Sigma-Aldrich Kft. · H-1067 Budapest **INDIA** · Sigma-Aldrich Co. · Bangalore 560 048 **IRELAND** · Sigma-Aldrich Ireland Ltd. · Dublin 24 **ISRAEL** · Sigma Israel Chemicals Ltd. · Rehovot 76100 **ITALY** · Sigma-Aldrich s.r.l. · 20151 Milano **JAPAN** · Sigma-Aldrich Japan K.K. · Chuo-ku, Tokyo 103 **KOREA** · Sigma-Aldrich Korea · Seoul **MALAYSIA** · Sigma-Aldrich (M) Sdn. Bhd. · 58200 Kuala Lumpur
MEXICO · Sigma-Aldrich Química S.A. de C.V. · 50200 Toluca **NETHERLANDS** · Sigma-Aldrich Chemie BV · 3330 AA Zwijndrecht **NORWAY** · Sigma-Aldrich Norway · Torshov · N-0401 Oslo
POLAND · Sigma-Aldrich Sp. z o.o. · 61-663 Poznań **PORTUGAL** · Sigma-Aldrich Quimica, S.A. · Sintra 2710 **RUSSIA** · Sigma-Aldrich Russia · Moscow 103062 **SINGAPORE** · Sigma-Aldrich Pte. Ltd.
SOUTH AFRICA · Sigma-Aldrich (pty) Ltd. · Jet Park 1459 **SPAIN** · Sigma-Aldrich Quimica, S.A. · 28100 Alcobendas, Madrid **SWEDEN** · Sigma-Aldrich Sweden AB · 135 70 Stockholm
SWITZERLAND · Supelco · CH-9471 Buchs **UNITED KINGDOM** · Sigma-Aldrich Company Ltd. · Poole, Dorset BH12 4QH
UNITED STATES · Supelco · Supelco Park · Bellefonte, PA 16823-0048 · Phone 800-247-6628 or 814-359-3441 · Fax 800-447-3044 or 814-359-3044 · email: supelco@sial.com

Supelco is a member of the Sigma-Aldrich family. Supelco products are sold through Sigma-Aldrich, Inc. Sigma-Aldrich warrants that its products conform to the information contained in this and other Sigma-Aldrich publications. Purchaser must determine the suitability of the product for a particular use. Additional terms and conditions may apply. Please see the reverse side of the invoice or packing slip.