

Promozioni Analitiche Sigma Aldrich

Autunno 2009

Discounts on Price, Not on Quality!
Fino al 30 novembre 2009

SAVE
25%




Fatty Acid Standard / Fame

Sigma Aldrich provides a large selection of high quality Supelco calibration solutions for FAME analysis.

Prod. No.	Description	Disc. %
47885-U	Supelco 37 Component Fame Mix, 1x1ml, CH ₂ CL ₂	25
07756-1AMP	F.A.M.E. Mix Rapeseed Oil, 100mg, Neat	25
47033	Pufa No.1, Marine Source, 100mg Neat	25
47015-U	Pufa No.2, Animal Source, 100mg Neat	25
47085-U	Pufa No.3, From Menhaden Oil, 100mg Neat	25

Visit sigma-aldrich.com/standard

SAVE
35%

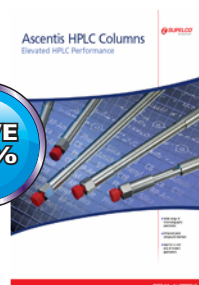

Ascentis® HPLC Columns

Ascentis bonded phases have a wide range of selectivities. It is likely that one or more Ascentis phase will accomplish any small molecule HPLC separation. Packed in micro to preparative hardware dimension, Ascentis products cover all HPLC application areas, including the most sensitive trace-level analyses.

Prod. No.	Description	Disc. %
581325-U	Ascentis C18 HPLC Column, 5 µm particle size, L x i.d. 25 cm x 4.6 mm	35
581322-U	Ascentis C18 HPLC Column, 3 µm particle size, L x i.d. 15 cm x 4.6 mm	35
565325-U	Ascentis RP-Amide HPLC column, 5 µm particle size, L x i.d. 25 cm x 4.6 mm	35
565322-U	Ascentis RP-Amide HPLC column, 3 µm particle size, L x i.d. 15 cm x 4.6 mm	35
581513-U	Ascentis Si HPLC Column, 5 µm particle size, L x i.d. 25 cm x 4.6 mm	35

Visit sigma-aldrich.com/express

SAVE
25%



Silylation Reagents for GC applications

Enhance your GC performance by modifying your sample using silylation reagents! Silylation is the most widely used derivatization technique. Nearly all functional groups which present a problem in gas chromatographic separation can be derivatized by silylation reagents. Sigma-Aldrich is offering more than 80 powerful silylation reagents.

Prod. No.	Description	Disc. %
69479	MSTFA (N-Methyl-N-trimethylsilyltrifluoroacetamide)	25
50992	MSTFA activated I (activated with ethanethiol and ammonium iodide)	25
15222	BSTFA (N,O-Bis(trimethylsilyl)trifluoroacetamide)	25
69484	MSHFBA (N-Methyl-N-trimethylsilylheptafluorobutyramide)	25
92751	TMCS (1-(Trimethylsilyl)imidazole)	25

Visit sigma-aldrich.com/silylation

Continued overleaf >>>

Promozioni Analitiche Sigma Aldrich

Autunno 2009



Offers continued...
Fino al 30 novembre 2009

SAVE
35%




SLB-5ms Capillary Columns

Today's chromatographers require GC-MS columns with consistent low bleed characteristics. High column bleed may interfere with proper mass spectral identification of analytes and may also foul the MS source. For these reasons, capillary columns that exhibit very low levels of bleed are desirable. Supelco SLB-5ms (Supelco low bleed) capillary columns offer: • Cleaner mass spectra • Lower detection limits < 3 pA at 325 °C • Shorter analysis times • Greater reproducibility, column-to-column.

Prod. No.	Description	Disc. %
28471-U	FS CAP SLB -5ms, 30m, 0.25mm, 0.25µm	35
28472-U	FS CAP SLB -5ms, 60m, 0.25mm, 0.25µm	35
28482-U	FS CAP SLB -5ms, 30m, 0.32mm, 0.25µm	35
28484-U	FS CAP SLB -5ms, 30m, 0.32mm, 0.50µm	35
28564-U	FS CAP SLB -5ms, 20m, 0.18mm, 0.18µm	35

Visit sigma-aldrich.com/gc

SAVE
30%

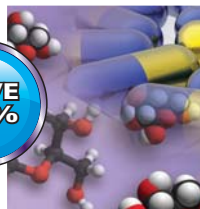

apHera HPLC columns

apHera HPLC columns - provide the efficiency of silica based columns but with the pH operating range of a polymer. A high performance, highly robust C18 polyvinyl alcohol 300 Å polymer with excellent aqueous compatibility makes it ideal for bases, peptides and proteins. An amino bonded version completes the range and is ideal for the separation of mono- and oligosaccharides.

Prod. No.	Description	Disc. %
56403AST	apHera NH2 Polymer HPLC Column, 5mm, 250 x 4.6mm	30
56400AST	apHera NH2 Polymer HPLC Column, 5mm, 150 x 2.0mm	30
56103AST	apHera C18 Polymer 300A HPLC Column, 5mm, 250 x 4.6mm	30
56202AST	apHera C8 Polymer 300A HPLC Column, 5mm, 150 x 4.6mm	30
56302AST	apHera C4 Polymer 300A HPLC Column, 5mm, 150 x 4.6mm	30

Visit sigma-aldrich.com/aphera_hplc

SAVE
25%



Supel-Select HLB SPE

Supel-Select HLB SPE is a hydrophilic modified styrene-based polymer developed for solid phase extraction (HLB: Hydrophilic Lipophilic Balance)

Prod. No.	Description	Disc. %
54181-U	Pk100 SUPEL-SELECT HLB 30mg/1ml SPE Tube	25
54182-U	Pk50 SUPEL-SELECT HLB 60mg/3ml SPE Tube	25
54183-U	Pk30 SUPEL-SELECT HLB 200mg/6ml SPE Tube	25
54184-U	Pk20 SUPEL-SELECT HLB 500mg/12 MI SPE Tube	25
54186-U	Pk20 SUPEL-SELECT HLB 1g/20ml SPE Tube	25
575661-U	Pk1 SUPEL-SELECT HLB 96-Well 30mg/Well	25
575662-U	Pk1 SUPEL-SELECT HLB 96-Well 60mg/Well	25

Visit sigma-aldrich.com/supel-select

When placing your order please quote promotion code **V26**

Offer valid until November 30th, 2009.

Trovera' l' elenco completo dei prodotti in promozione al link :

sigma-aldrich.com

LTV 9/10.2009

SIGMA-ALDRICH®