


Featured Products

DNA Ladders you can count on!

NEB offers high quality DNA Ladders with sizes ranging from 25 bp to 10 kb for use in agarose gel electrophoresis. NEB is happy to announce recent advantages in production that led to reduced list prices and therefore reduced cost per gel lane!

Advantages:

- Stable at room temperature
- Sharp uniform bands
- Easy-to-identify reference bands
- Can be used for sample quantitation
- Convenience:
 - TriDye™ ladders are ready-to-use (contain three dyes to monitor migration)
 - Quick-Load® ladders are ready-to-use (contain bromophenol blue for tracking)
- All “regular” ladders are supplied with supplemental loading buffer

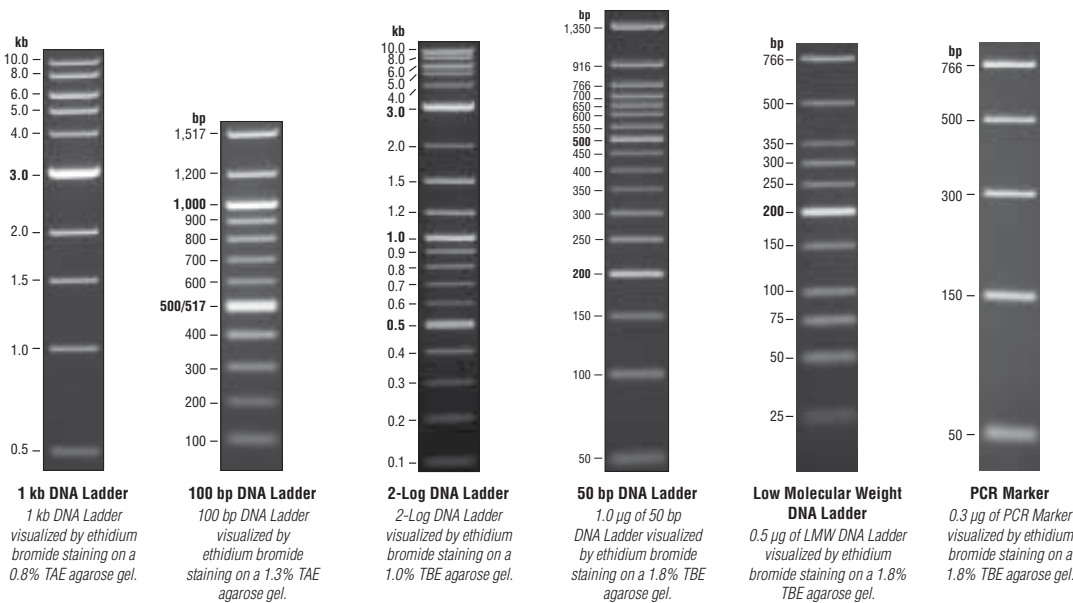

a.) TriDye™ DNA Ladders



TriDye™ DNA Ladders are prediluted in gel loading buffer containing xylene cyanol FF, bromophenol blue and orange G (runs at approximately 50 bp in regular 1% TBE gels)

b.) Quick-Load® DNA Ladders



Quick-Load® DNA Ladders are prediluted in gel loading buffer containing bromophenol blue.

DNA Ladder/Marker	Catalog #	Range	Supplied with loading dye	Quantitation	gel lanes	
					S	L
1 kb DNA Ladder	N3232S/L	0.5–10.0 kb	✓	✓	200	1000
	TriDye	N3272S	Ready-to-use	✓	125	-
	Quick-Load	N0468S/L	Ready-to-use	✓	125	375
100 bp DNA Ladder	N3231S/L	100–1,517 bp	✓	✓	100	500
	TriDye	N3271S	Ready-to-use	✓	125	-
	Quick-Load	N0467S/L	Ready-to-use	✓	125	375
2-Log DNA Ladder	N3200S/L	0.1–10.0 kb	✓	✓	100	500
	TriDye	N3270S	Ready-to-use	✓	125	-
	Quick-Load	N0469S/L	Ready-to-use	✓	125	375
	Biotinylated	N7554S	Ready-to-use	✓	25	-
50 bp DNA Ladder	N3236S/L	50–1,350 bp	✓	✓	100	500
Low MW DNA Ladder	N3233S/L	25–766 bp	✓	✓	100	500
PCR Marker	N3234S/L	50–766 bp	✓	✓	100	500

Free Poster

Ladders you can count on!

Receive your free poster featuring all DNA, RNA and Protein Markers from NEB!



- ▶ For time-saving and convenience combined with optimal migration control during electrophoresis choose NEB's **ready-to-use ladder formats** prediluted in loading buffer containing tracking dyes!



Order now and receive a **35% discount** on any **DNA Ladder** (limited offer).

Test NEB's high quality ladders in your application:

*Request a **free** “ready-to-use”

Quick-Load® Sample Pack containing the 1 kb and the 100 bp ladder!

Contact your local distributor for details (limited offer)!

New Protein Ladders you can count on!


The Protein Ladder is a mixture of recombinant, highly purified proteins that resolve into 12 sharp, evenly spaced bands when analyzed by SDS-PAGE. The Protein Ladder is now available in three convenient formats: unstained for accurate molecular weight determination, prestained, and prestained with two additional colored bands for easy identification.

Advantages:


- Suitable for analysis of a wide range of proteins
- Uniform band intensities
- Convenient band spacing
- Easy-to-identify reference bands



PRODUCT	NEB #	SIZE
Protein Ladder (10-250 kDa)	P7703S	100 mini-gel lanes
Prestained Protein Ladder, Broad Range (10-230 kDa)	P7710S	100 mini-gel lanes
ColorPlus Prestained Protein Ladder, Broad Range (10-230 kDa)	P7711S	100 mini-gel lanes

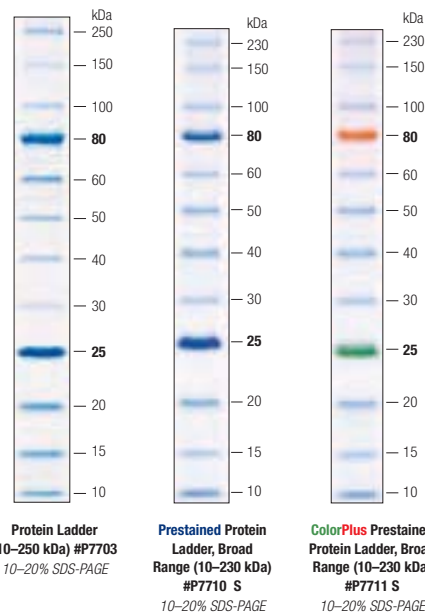

Choose the NEB ladder for sharp, evenly spaced bands, convenient band spacing and choice of formats.
 (A) Prestained Protein Ladder (NEB #P7710),
 (B) ColorPlus Prestained Protein Ladder (NEB #P7711).

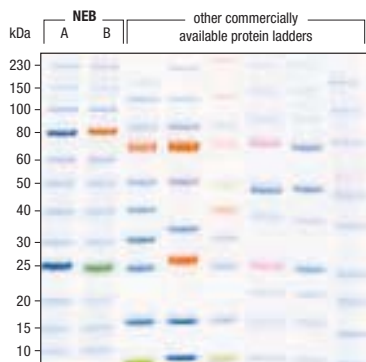

► Order now and receive a **35% discount** on any of the three **new Protein Ladders**.
 Contact your local distributor for details (limited offer)!

all offer close October, 31th, 2009!



Contact your local distributor:

Sigma-Aldrich Norway AS
 Tevlingveien 23
 Postboks 188 Leirdal
 N-1011 Oslo

Telefon: 23 17 60 60
 Fax: 23 17 60 50
 E-mail: NorOrder@sial.com

