


Product Specification

Product Name:

Penicillin-Streptomycin - Solution Stabilized, with 5,000 units penicillin and 5mg streptomycin/mL, sterile-filtered, BioReagent, suitable for cell culture

Product Number:

P4458

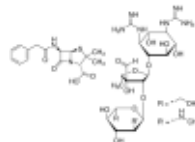

Storage Temperature:

-20 °C

TEST	Specification
Appearance (Form)	Liquid
Appearance (Turbidity)	Clear
Osmolality	
Penicillin (U/ml)	5000 - 6000
Potency Streptomycin	5 - 6 mg/ml
Endotoxin Level at 20ml/Lt	≤ 0.5 EU/ml
Cell Line	Hep-2 Human Cells
Cell Culture Test	≥ 50 %
percent of control	
Expiration Date Period	-----
24 months	

Specification: PRE.1.ZQ5.10000014847

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at Sigma-Aldrich.com. For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.

