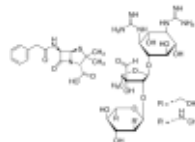


## Product Specification

**Product Name:**

Penicillin-Streptomycin - Solution stabilized, with 10,000 units penicillin and 10 mg streptomycin/mL, sterile-filtered, BioReagent, suitable for cell culture

**Product Number:**
**P4333**

**Storage Temperature:**
**-20 °C**

TEST	Specification
Appearance (Form)	Liquid
Appearance (Turbidity)	Clear
Osmolality	
Penicillin (U/ml)	10000 - 12000
Potency Streptomycin	10 - 12 mg/ml
Endotoxin Level at 10ml/L	≤ 0.5 EU/ml
Cell Line	Hep-2 Human Cells
Cell Culture Test	≥ 50 %
percent of control	
Expiration Date Period	-----
24 months	

Specification: PRE.1.ZQ5.10000014726

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at [Sigma-Aldrich.com](http://Sigma-Aldrich.com). For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.

