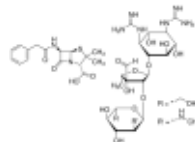


## Product Specification

**Product Name:**

Penicillin-Streptomycin - with 10,000 units penicillin and 10 mg streptomycin per mL in 0.9% NaCl, sterile-filtered, BioReagent, suitable for cell culture

**Product Number:**
**P0781**

**Storage Temperature:**
**-20 °C**

TEST	Specification
Appearance (Form)	Liquid
Appearance (Turbidity)	Clear
Osmolality	306.0 - 374.0 mOs/kg
Penicillin (U/ml)	10000 - 12000
Potency Streptomycin	10 - 12 mg/ml
Endotoxin Level at 10ml/L	≤ 0.5 EU/ml
Cell Culture Test Cell Line	Hep-2 Human Cells
Cell Culture Test percent of control	≥ 50.0 %
Expiration Date Period 18 Months	-----

Specification: PRE.1.ZQ5.10000015197

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at [Sigma-Aldrich.com](http://Sigma-Aldrich.com). For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.

