

3050 Spruce Street, Saint Louis, MO 63103, USA


Website: www.sigmaaldrich.comEmail USA: techserv@sial.comOutside USA: eurtechserv@sial.com

Product Specification

Product Name:
3-*epi*-25-Hydroxyvitamin D₂ solution - 100 µg/mL in ethanol, 98% (CP)

Product Number: 753556

Formula: C₂₈H₄₄O₂
Formula Weight: 412.65 g/mol
Storage Temperature: -20 °C

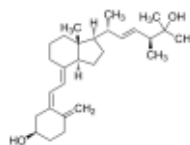

TEST	Specification
Appearance (Clarity)	Clear
Appearance (Color)	Colorless
Appearance (Form)	Solution
Purity (HPLC)	≥ 98.0 %
Proton NMR Spectrum	Conforms
Mass Spectrometry	Conforms
Concentration	90.0 - 110.0 µg/ml

Specification: PRD.0.ZQ5.10000058802

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at Sigma-Aldrich.com. For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.